

Your First Choice(s)

Try these elite leak-tight Swagelok performers to substantially boost your fluid-system safety, productivity, and profitability – in even your most challenging applications and operating conditions:

C, CA, CH, CP, AND CPA SERIES CHECK VALVES

- For working pressures up to 6000 psig
- For adjustable and fixed cracking pressures
- Available with a vast variety of end connections
- Made of premium 316 stainless steel and brass materials
- Other styles available



PROPORTIONAL, PRESSURE REGULATOR, AND BLEED-AND-PURGE RELIEF VALVES

- Provide overpressure protection with an array of set pressures offered
- Numerous styles available, plus spare parts and accessories



GU SERIES NEEDLE VALVES

- Straight and angle patterns
- Made of premium stainless steel and carbon steel body material
- For working pressures up to 6000 psig
- For temperatures up to 450° F with PTFE packing; up to 650° F with optional graphite packing
- Other styles available



QUICK-CONNECTS

- Enable quick, simple operation without twisting, turning, or wrenching
- Design minimizes spillage and air inclusion
- Push-to-connect
- Instrumentation, single-end shutoff, double-end shutoff, full-flow, miniature, and PTFE-sealed styles



GAUGES

- Available for ultra-high purity, panel builders, general purpose
- Precise, on-demand pressure, temperature, and flow readings



PRESSURE TRANSDUCERS

- Maintain accurate electronic pressure monitoring
- For general industrial applications
- Explosion-proof, intrinsically safe



SAMPLE CYLINDERS

- Protect product integrity during transport
- Consistent wall thickness
- Smooth internal neck transitions ensure easy cleaning
- Heavy-wall connections resist flaring



ORBITAL WELDING SYSTEMS

- Delivers cost-effective, repeatable tungsten arc welds
- Lightweight, portable M200 power supply
- Easy-to-use touchscreen operation
- Accessories: weld heads, fixture blocks, side plates, collets...



...AND SO MUCH MORE:


Instrumentation Panels, Tube Fittings, Industrial Hose, Tubing, Regulators, Filters...!

WE'RE YOUR TRUSTED & PROVEN

Local Resource for the genuine Swagelok Products and Services that will improve your Bottom-Line health – unparalleled Tube Fittings to comprehensive Safety Training to unmatched Technical Expertise to masterful Design & Build capabilities, to...

Find out today how we can specifically help you stay on-time, on-plan, and on-budget:

Tony Del Bianco,
Direct Sales Representative

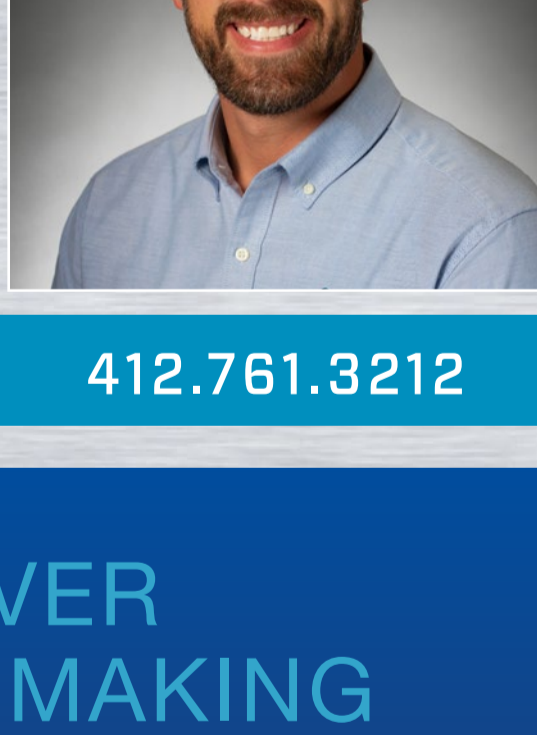

tony.delbianco@swagelok.com

412.761.3212



WE DELIVER DIFFERENCE-MAKING SOLUTIONS:

Products | Strategic Support Services | Application Know-How



The Brand. The Inventory. The Expertise.

WE'RE YOUR SWAGELOK FLUID-SYSTEM SOLUTIONS PROVIDER

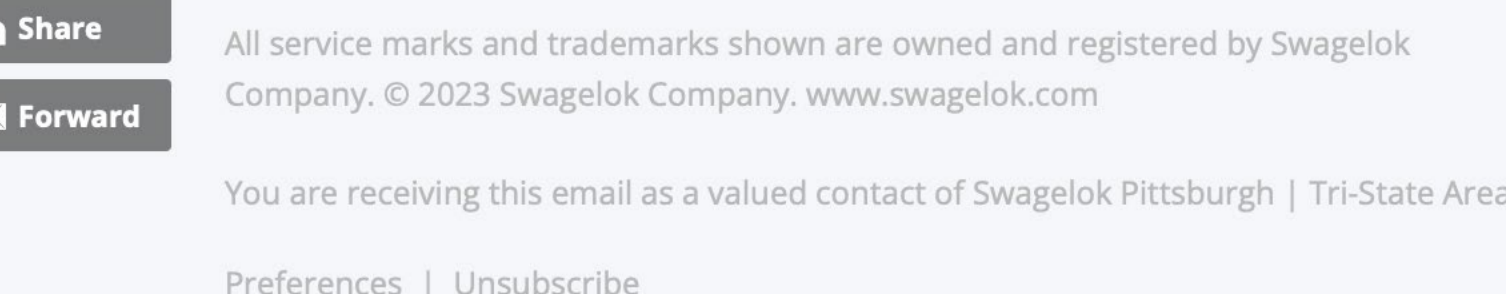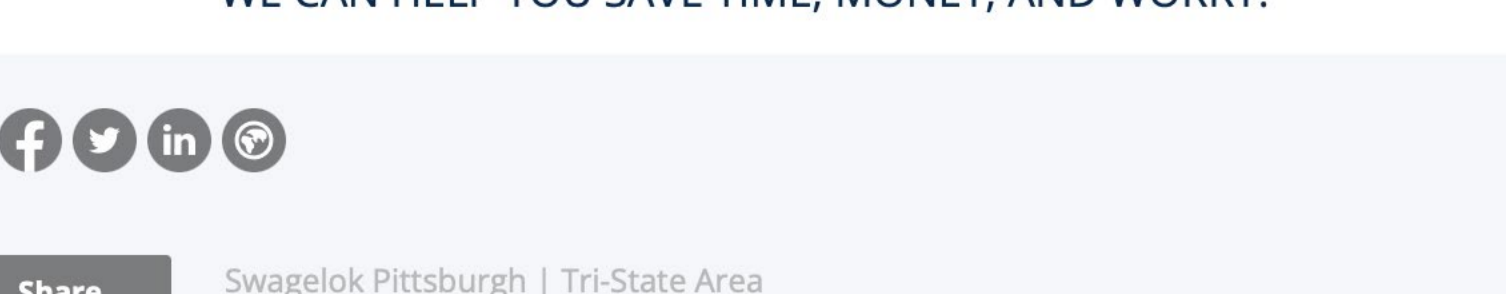

WE CAN HELP YOU SAVE TIME, MONEY, AND WORRY:

Share

Swagelok Pittsburgh | Tri-State Area

Tweet

49 Meade Avenue, Pittsburgh, PA 15202
412.761.3212

in Share

All service marks and trademarks shown are owned and registered by Swagelok Company. © 2023 Swagelok Company. www.swagelok.com

Forward

You are receiving this email as a valued contact of Swagelok Pittsburgh | Tri-State Area.

[Preferences](#) | [Unsubscribe](#)